

Toughbay™ Circular 230W

Direct replacement for 400W HID metal halide

- 5 year extended warranty, including 2 year on-site support
- 105° beam angle without reflector
- Supplied with mounting ring and IP67 connector as standard
- 60° reflector beam angle option
- Suitable for high mounting industrial applications
- IP65 - Suitable for areas with high salt/moisture content
- 1-10V dimmable as standard



5 year ext. warranty*
(inc. 2 year on site)



Dimmable
as standard



Emergency
options available



Classification

Class 1
IP65 | 240V

LED

5700K | CRI: Ra (80)

Finishes

Black


Construction

Body: Aluminium
Lens: Polycarbonate


Accessories

IP65 Connector, 60° beam reflector, Surface mount bracket (see p.113)

JC71812

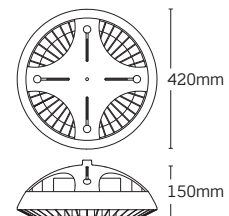

JC71812EM

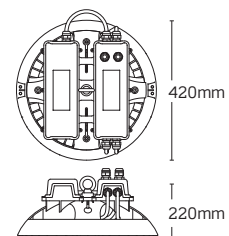

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC71812BLK	Toughbay Circular	5700K	Yes	230W	23,700	103
JC71812BLKEM	Toughbay Circular emergency	5700K	Yes	230W	23,700	103

*Requires online registration.

All data sheets and installation sheets available at jcc.co.uk