

Toughbay™ Retrofit 100 & 150W

150W and 250W HID replacement

- Ultra efficient, 123 lumens per circuit Watt
- High CRI of 80, ensuring a true representation of colour
- Suitable for wide range of operating temperatures, -30° to +60°
- Step dimming available with remote control (see p.335)
- 1-10V dimmable as standard
- 60° and 90° beam angle options available




NEW New product for 2018

5 year ext. warranty*

60° / 90° beam angle options

Dimmable as standard

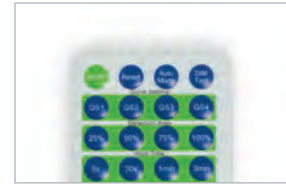

LEV71805 (see p.335)



JC71840 / JC71841

Classification

Class 1
IP65 | 240V

LED

5700K | CRI: Ra (80)


Finishes

Black


Construction

Body: Aluminium
Lens: Polycarbonate
Bracket: Steel

JC71830/60/90

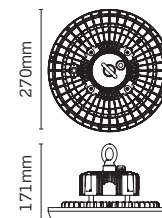

JC71831/60/90

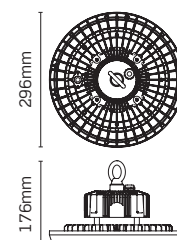

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC71830/60	Toughbay Retrofit 60°	5700K	Yes	100W	12,300	123
JC71830/90	Toughbay Retrofit 90°	5700K	Yes	100W	12,300	123
JC71830/60MW	Toughbay Retrofit 60° micro. dim.	5700K	-	100W	12,300	123
JC71830/90MW	Toughbay Retrofit 90° micro. dim.	5700K	-	100W	12,300	123
JC71831/60	Toughbay Retrofit 60°	5700K	Yes	150W	18,400	123
JC71831/90	Toughbay Retrofit 90°	5700K	Yes	150W	18,400	123
JC71831/60MW	Toughbay Retrofit 60° micro. dim.	5700K	-	150W	18,400	123
JC71831/90MW	Toughbay Retrofit 90° micro. dim.	5700K	-	150W	18,400	123
JC71840	Bracket for 100W	-	-	-	-	-
JC71841	Bracket for 150W	-	-	-	-	-
LEV71805	Toughbay Microwave Remote	-	-	-	-	-

*Requires online registration.

All data sheets and installation sheets available at jcc.co.uk