



Toughbay™ Retrofit 200W

400W HID replacement

NEW New product for 2018

 5 year ext. warranty*

 60° / 90° beam angle options

 Dimmable as standard

- Ultra efficient, 122 lumens per circuit Watt
- High CRI of 80, ensuring a true representation of colour
- Suitable for wide range of operating temperatures, -30° to +60°
- Step dimming available with remote control (see p.335)
- 1-10V dimmable as standard
- 60° and 90° beam angle options available




▲ LEV71805 (see p.335)
Toughbay microwave remote



▲ JC71842
Surface mount bracket

Classification

 Class 1
IP65 | 240V

LED

5700K | CRI: Ra (80)


Finishes

Black

Construction

Body: Aluminium
Lens: Polycarbonate
Bracket: Steel

JC71832/60/90

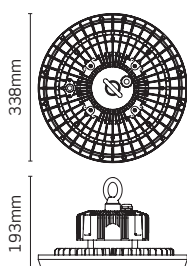

All data sheets and installation sheets available at jcc.co.uk



Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC71832/60	Toughbay Retrofit 60°	5700	Yes	200W	24,500	122
JC71832/90	Toughbay Retrofit 90°	5700	Yes	200W	24,500	122
JC71832/60MW	Toughbay Retrofit 60° micro. dim.	5700	-	200W	24,500	122
JC71832/90MW	Toughbay Retrofit 90° micro. dim.	5700	-	200W	24,500	122
JC71842	Bracket for 200W	-	-	-	-	-
LEV71805	Toughbay Microwave Remote	-	-	-	-	-

*Requires online registration.