

Toughbay™ High Output 100W

Outperforms traditional HID light outputs

NEW

New product for 2018



7 year ext. warranty* (inc. 2 year on site)



60° / 90° beam angle options



See p.334 mic. sensor and remote



LEV71805 (see p.335)
Toughbay microwave remote



JC71840
Surface mount bracket

Classification

Class 1
IP65 | 240V

LED

5700K | CRI: Ra (80)


Finishes

Black

Construction

Body: Aluminium
Lens: Polycarbonate
Bracket: Steel

JC71833

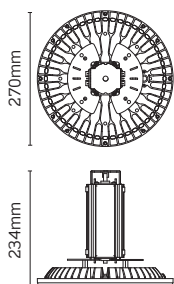

All data sheets and installation sheets available at jcc.co.uk

- Ultra efficient, 145 lumens per circuit Watt
- High CRI of 80, ensuring a true representation of colour
- Suitable for a wide range of operating temperatures, -30° to +60°
- Step dimming available with remote control (see p.335)
- Suitable for relative humidity levels of up to 90%
- 7 year extended warranty including 2 years on site support



Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC71833/60	Toughbay High Output 60°	5700K	Yes	100W	14,500	145
JC71833/90	Toughbay High Output 90°	5700K	Yes	100W	14,500	145
JC71833/60MW	Toughbay High Output 60° micro. dim.	5700K	-	100W	14,500	145
JC71833/90MW	Toughbay High Output 90° micro. dim.	5700K	-	100W	14,500	145
JC71840	Bracket for 100W high output	-	-	-	-	-
LEV71805	Toughbay microwave remote	-	-	-	-	-

*Requires online registration.