


Toughbay™ High Output 150W


Outperforms 250W HID


- Ultra efficient, 141 lumens per circuit Watt
- High CRI of 80, ensuring a true representation of colour throughout its life
- Suitable for a wide range of operating temperatures, -30° to +60°
- Step dimming available with remote control (see p.335)
- Suitable for relative humidity levels of up to 90%
- 7 year extended warranty including 2 years on site support





NEW New product for 2018

 7 year ext. warranty* (inc. 2 year on site)

 60° / 90° beam angle options

 See p.334 mic. sensor and remote

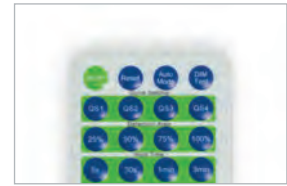


 **LEV71805** (see p.335)
Toughbay microwave remote



 **JC71844**
Surface mount bracket

Classification

 Class 1
IP65 | 240V

LED

5700K | CRI: Ra (80)


Finishes

Black

Construction

Body: Aluminium
Lens: Polycarbonate
Bracket: Steel

JC71834

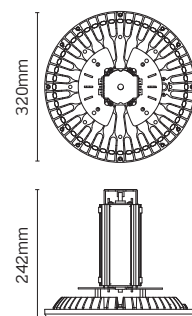

| Code | Description | Col temp. | Dim. | Watt | Lumens | LpcW |
|--------------|--------------------------------------|-----------|------|------|--------|------|
| JC71834/60 | Toughbay High Output 60° | 5700K | Yes | 150W | 21,200 | 141 |
| JC71834/90 | Toughbay High Output 90° | 5700K | Yes | 150W | 21,200 | 141 |
| JC71834/60MW | Toughbay High Output 60° micro. dim. | 5700K | - | 150W | 21,200 | 141 |
| JC71834/90MW | Toughbay High Output 90° micro. dim. | 5700K | - | 150W | 21,200 | 141 |
| JC71844 | Bracket for 150W high output | - | - | - | - | - |
| LEV71805 | Toughbay microwave remote | - | - | - | - | - |

*Requires online registration.

All data sheets and installation sheets available at jcc.co.uk