




# Toughbay™ High Output 200W

## Outperforms 400W HID


**NEW** New product for 2018

 7 year ext. warranty\* (inc. 2 year on site)

 60° / 90° beam angle options

 See p.334 mic. sensor and remote




 **LEV71805** (see p.335)  
Toughbay microwave remote



 **JC71845**  
Surface mount bracket

### Classification

 Class 1  
IP65 | 240V

### LED

5700K | CRI: Ra (80)


### Finishes

Black

### Construction

Main chassis: Aluminium  
Lens: Polycarbonate  
Bracket: Steel

### JC71835

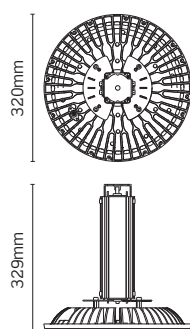

All data sheets and installation sheets available at [jcc.co.uk](http://jcc.co.uk)

- Ultra efficient, 140 lumens per circuit Watt
- High CRI of 80, ensuring a true representation of colour throughout its life
- Suitable for a wide range of operating temperatures, -30° to +60°
- Step dimming available with remote control (see p.335)
- Suitable for relative humidity levels of up to 90%
- 7 year extended warranty including 2 years on site support



Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC71835/60	Toughbay High Output 60°	5700K	Yes	200W	28,000	140
JC71835/90	Toughbay High Output 90°	5700K	Yes	200W	28,000	140
JC71835/60MW	Toughbay High Output 60° micro. dim.	5700K	-	200W	28,000	140
JC71835/90MW	Toughbay High Output 90° micro. dim.	5700K	-	200W	28,000	140
JC71845	Bracket for 200W high output	-	-	-	-	-
LEV71805	Toughbay microwave remote	-	-	-	-	-

\*Requires online registration.