

NEW New product for 2018



7 year ext. warranty*



50°/80°/30°x60° beam angle options



Microwave versions available



Dimmable as standard



See p.334 mic. sensor and remote



LEV71805 (see p.335)
Toughbay microwave remote

Classification

Class 1
IP65 | 240V

LED

5700K | CRI: Ra (70)

Finishes

Black


Construction

Body: Aluminium
Lens: Polycarbonate

Accessories

Microwave remote control
(see p.335)

JC71931

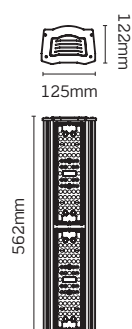

All data sheets and installation sheets available at jcc.co.uk

Toughbay™ Linear 100W

Outperforms traditional HID Lowbay

- Ultra efficient up to 140 lumens per circuit Watt
- IP65 protection against dust and moisture
- Multiple lenses available
- 1-10V dimmable as standard
- 30°x60° lens option, suitable for racking applications
- Step dimming available with remote control (see p.335)
- Suitable for a wide range of operating temperatures, -30° to +60°



Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC71931/30X60	Toughbay Linear 30°x60°	5700K	Yes	100W	14,000	140
JC71931/30X60MW	Toughbay Linear 30°x60° micro.	5700K	-	100W	14,000	140
JC71931/50	Toughbay Linear 50°	5700K	Yes	100W	14,000	140
JC71931/50MW	Toughbay Linear 50° micro.	5700K	-	100W	14,000	140
JC71931/80	Toughbay Linear 80°	5700K	Yes	100W	14,000	140
JC71931/80MW	Toughbay Linear 80° micro.	5700K	-	100W	14,000	140
LEV71805	Toughbay microwave remote	-	-	-	-	-

*Requires online registration.