



New product
for 2018



3 year ext. warranty
(batteries 2 years)*

Exit Box

Direct 8W T5 retrofit LED exit box

- Visible from a distance of 24 metres
- Supplied as standard with down running man legend
- Left/right or up running man legends bought separately
- Top and rear conduit entry knock out points
- Suitable for use as maintained and non maintained

✓ JC50303 (Shown with JC50304)



✓ JC50322 (Shown with JC50329)



Classification

⚡ Class 1
IP20 | 240V

LED

6000K | CRI: Ra (80)


Finishes

White


Construction

Body: Painted steel (JC50303),
Polycarbonate (JC50322),
Acrylic (Running man legend)
Diffuser: Polycarbonate

JC50303

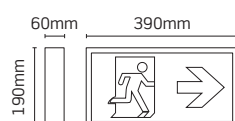

JC50322

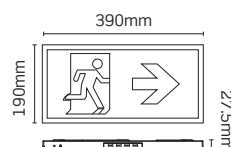

All data sheets and installation sheets
available at jcc.co.uk

Code	Description	Col temp.	Watt	Lumens DC	Lumens AC
JC50303	Exit Box with down arrow**	6000K	6W	48	95
JC50304	Left & right running legend for JC50303	-	-	-	-
JC50314	Up running legend for JC50303	-	-	-	-
JC50322	Self Test Exit Box	6000K	3W	40	40
JC50329	Left/Right/Up legend for JC50322	-	-	-	-

** Running man legend kits bought separately

*Requires online registration.