

Architectural Pendant 10W

Decorative interior LED pendant

- Stylish, ultra modern design
- Pre-wired with three-core cable and a braided outer sleeving
- Triac dimmable as standard
- Available in white and black finishes
- Up to 91 lumens per circuit Watt



NEW

New product
for 20185 year
ext. warranty*36°
beam angleDimmable
as standard

JC84210BLK

Classification

Class 1
IP20 | 240V

LED

3000K | CRI: Ra (80)
4000K | CRI: Ra (80)


Finishes

Black (**BLK**), White (**WH**)

Construction

Body: Aluminium
Lens: Glass

JC84211

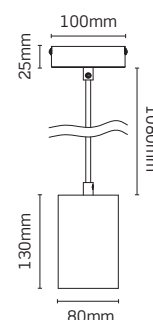

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC84210	Architectural LED Pendant	3000K	Yes	10W	870	87
JC84211	Architectural LED Pendant	4000K	Yes	10W	910	91

For Black add **BLK** suffix, for White add **WH** suffix.

*Requires online registration.

All data sheets and installation sheets
available at jcc.co.uk