


NEW New product for 2018

 5 year ext. warranty*


 36° beam angle

 Dimmable as standard



 JC84212BLK

Classification

 Class 1
IP20 | 240V

LED

3000K | CRI: Ra (80)
4000K | CRI: Ra (80)


Finishes

Black (**BLK**), White (**WH**)

Construction

Body: Aluminium
Lens: Glass

JC84213

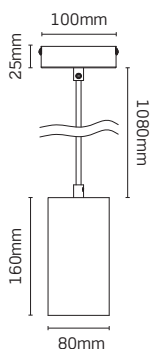

All data sheets and installation sheets available at jcc.co.uk

Architectural Pendant 18W

Decorative interior LED pendant

- Stylish, ultra modern design
- Pre-wired with three-core cable and a braided outer sleeving
- Triac dimmable as standard
- Available in white and black finishes
- Up to 89 lumens per circuit Watt



 JC84212WH

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC84212	Architectural LED Pendant	3000K	Yes	18W	1500	83
JC84213	Architectural LED Pendant	4000K	Yes	18W	1600	89

For Black add **BLK** suffix, for White add **WH** suffix.

*Requires online registration.