

Architectural Pendant 25W

Decorative interior LED pendant

- Stylish, ultra modern design
- Pre-wired with three-core cable and a braided outer sleeving
- Triac dimmable as standard
- Available in white and black finishes
- Up to 80 Lumens per circuit Watt



NEW New product for 2018

5 year ext. warranty*

36° beam angle

Dimmable as standard



Classification

Class 1
IP20 | 240V

LED

3000K | CRI: Ra (80)
4000K | CRI: Ra (80)


Finishes

Black (**BLK**), White (**WH**)

Construction

Body: Aluminium
Lens: Glass

JC84215

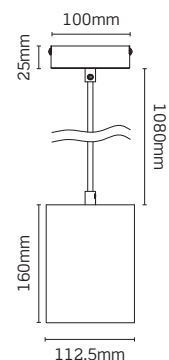

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC84214	Architectural LED Pendant	3000K	Yes	25W	1950	78
JC84215	Architectural LED Pendant	4000K	Yes	25W	2000	80

For Black add **BLK** suffix, for White add **WH** suffix.

*Requires online registration.

All data sheets and installation sheets available at jcc.co.uk