

Starscoop™ High Output

High performance 20W commercial LED display light

- Ultra efficient, up to 117 lumens per circuit Watt
- Available in both black and white finishes
- Zero maintenance, no need to relamp
- Lifelong consistent colour temperature and rendering
- Available in 24°, 45° and 60° beam angles
- Produced to order, contact JCC customer services on **01243 838999**

✓ JC47446BLK



✓ JC47446WH



NEW

New product
for 20185 year
ext. warranty*24°/45°/60°
beam angle optionsEmergency
options availableProduced to order
call 01243 838999

Classification

Class 2
Class 1 (EM00172)
IP20 | 240V

LED

3000K | CRI: Ra (80)
4000K | CRI: Ra (80)

Finishes

Black (BLK), White (WH)


 
Construction

Body: Aluminium
Lens: Glass

Installation

Cut out Ø: 120-130mm

JC47443 / JC47446 / JC47444 /
JC47447 / JC47445 / JC47448

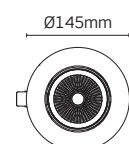

All data sheets and installation sheets
available at jcc.co.uk

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC47443	Starscoop 24°	3000K	No	20W	2230	112
JC47446	Starscoop 24°	4000K	No	20W	2330	117
JC47444	Starscoop 45°	3000K	No	20W	2230	112
JC47447	Starscoop 45°	4000K	No	20W	2330	117
JC47445	Starscoop 60°	3000K	No	20W	2230	112
JC47448	Starscoop 60°	4000K	No	20W	2330	117
EM00172	Plug and Play Emergency Pack	-	-	-	-	-

Products available to order, contact JCC customer services on **01243 838999**.

For Black add **BLK** suffix, for White add **WH** suffix.

*Requires online registration.