



New product
for 2018



5 year
ext. warranty*



24°/45°/60°
beam angle options



Emergency
options available



Produced to order
call 01243 838999

Starscoop™ High Output

High performance 35W commercial LED display light

- Ultra efficient, up to 114 lumens per circuit Watt
- Available in both black and white finishes
- Zero maintenance, no need to relamp
- Lifelong consistent colour temperature and rendering
- Available in 24°, 45° and 60° beam angles
- Produced to order, contact JCC customer services on **01243 838999**

✓ JC47452BLK



✓ JC47452WH



Classification

- ☐ Class 2
 - ☒ Class 1 (EM**00172**)
- IP20 | 240V

LED

3000K | CRI: Ra (80)
4000K | CRI: Ra (80)

Finishes

Black (**BLK**), White (**WH**)


Construction

Body: Aluminium
Lens: Glass

Installation

Cut out Ø: 165-170mm

JC47449 / JC47452 / JC47450 /
JC47453 / JC47451 / JC47454

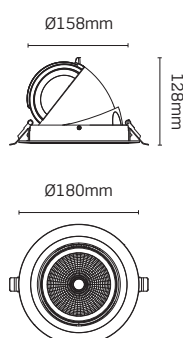

All data sheets and installation sheets
available at jcc.co.uk

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC47449	Starscoop 24°	3000K	No	35W	3780	108
JC47452	Starscoop 24°	4000K	No	35W	4000	114
JC47450	Starscoop 45°	3000K	No	35W	3780	108
JC47453	Starscoop 45°	4000K	No	35W	4000	114
JC47451	Starscoop 60°	3000K	No	35W	3780	108
JC47454	Starscoop 60°	4000K	No	35W	4000	114
EM00172	Plug and Play Emergency Pack	-	-	-	-	-

Products available to order, contact JCC customer services on **01243 838999**.

For Black add **BLK** suffix, for White add **WH** suffix.

*Requires online registration.