


 5 year
ext. warranty*

 40°
beam angle

Starspot™ 1500


High performance LED spotlights

- Life long consistent colour rendering
- No UV, ideal for retail applications
- High performance COB LED module
- 40° beam angle



^ JC14157WH

Classification

 Class 1
IP20 | 240V

LED

3000K | CRI: Ra (85)
4000K | CRI: Ra (85)

Finishes

Black (**BLK**), White (**WH**)


Construction

Body: Aluminium
Lens: Polycarbonate

Installation

Method of fix: Fixed to Single
Circuit Track or Three Circuit with
JC88118

JC14156 / JC14157

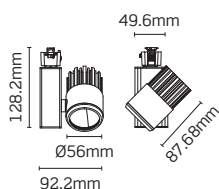

All data sheets and installation sheets
available at jcc.co.uk

✓ JC14157BLK



Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC14157	Starspot 1500	3000K	No	20W	1300	65
JC14156	Starspot 1500	4000K	No	20W	1500	75

For Black add **BLK** suffix, for White add **WH** suffix.

*Requires online registration.