

Starspot™ 3000

High performance LED spotlights

- Up to 88 lumens per circuit Watt
- No UV and virtually no radiated heat
- Instant start up, no warm up time
- Available in 15° and 38° beam angles

✓ JC14204WH



5 year
ext. warranty*



15°/38°
beam angle



✓ JC14204BLK

Classification

⚡ Class 1
IP20 | 240V

LED

3000K | CRI: Ra (85)
4000K | CRI: Ra (85)

Finishes

Black (**BLK**), White (**WH**)


Construction

Body: Aluminium
Lens: Polycarbonate

Installation

Method of fix: Fixed to Single
Circuit Track or Three Circuit with
JC88118

JC14200 / JC14201 / JC14204
/ JC14205

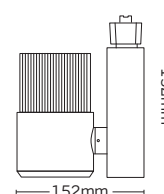

All data sheets and installation sheets
available at jcc.co.uk

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC14204	Starspot 3000 15°	3000K	No	34W	2800	83
JC14205	Starspot 3000 15°	4000K	No	34W	3000	88
JC14200	Starspot 3000 38°	3000K	No	34W	2800	83
JC14201	Starspot 3000 38°	4000K	No	34W	3000	88

For Black add **BLK** suffix, for White add **WH** suffix.

*Requires online registration.