


# Three Circuit Track Accessories

## Three circuit flexible track system fittings

- Three circuit flexible track system for retail and display applications
- Available in black or white
- Suitable for use with three circuit track adapter (JC88118)
- 20 amp max

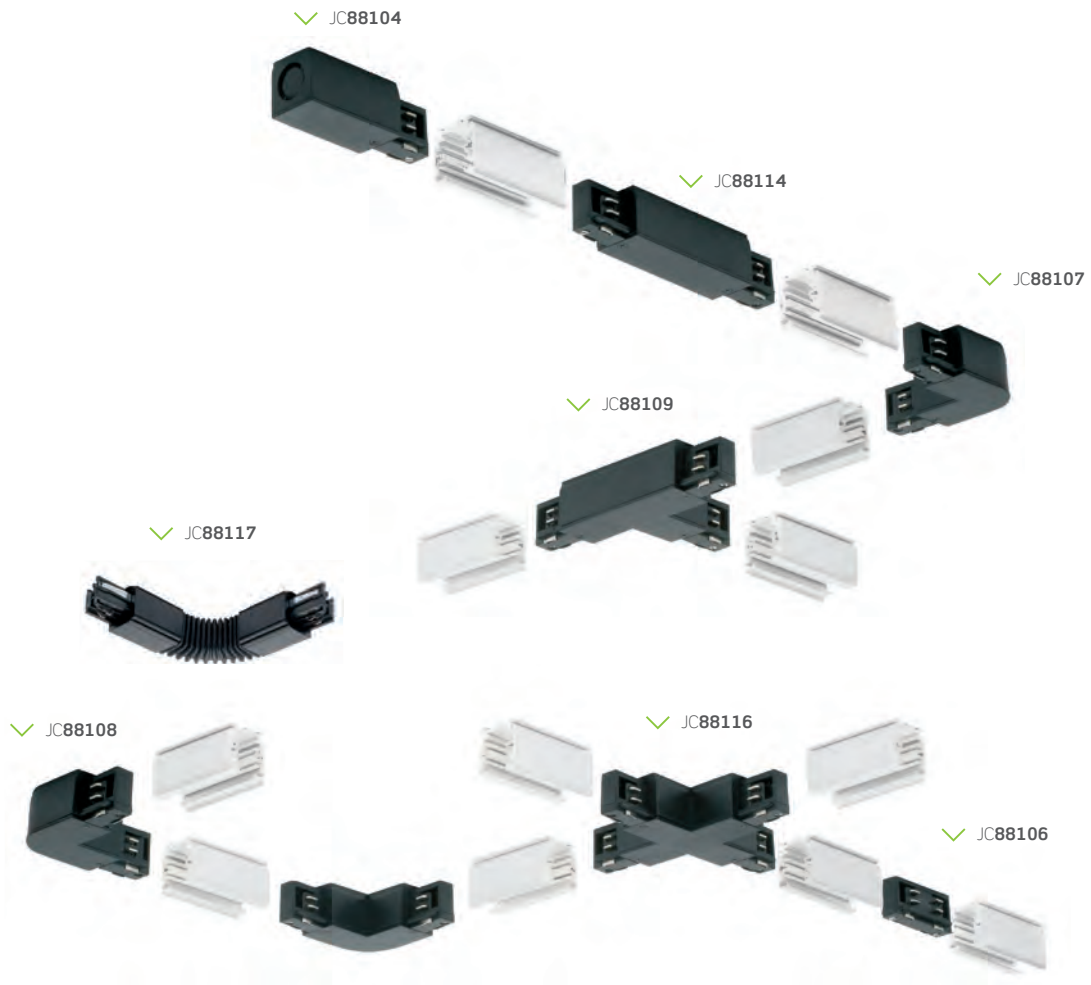

### Classification

Ⓜ Class 1  
IP20 | 240V | 20 amp max


### Finishes

Black (**BLK**), White (**WH**)

### Construction

Body: Aluminium

### JC88103

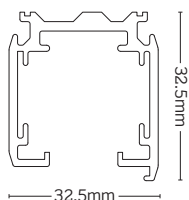

All data sheets and installation sheets available at [jcc.co.uk](http://jcc.co.uk)

Code	Description
JC88104	Power feed - right
JC88105	Power feed - left
JC88106	Concealed track connector
JC88107	L connector - right sided earth
JC88108	L connector - left sided earth
JC88109	T connector - right sided earth
JC88110	T connector - left sided earth
JC88112	End cap
JC88113	Ceiling bracket connector*
JC88114	Track connector with power feed
JC88115	Wire suspension kit* 1.5m
JC88116	Crossover connector
JC88117	Flexible elbow connector
JC88118	Three circuit track adapter (10amp max)

For Black add **BLK** suffix, for White add **WH** suffix.

\*Only available in White (**WH**)



- ✓ To convert any single circuit spotlight into a three circuit option, please order our adapter, **JC88118**