

Starspot™ 500 Surface Single

High performance LED surface mounted spotlights

- Exceeds 50W halogen light output
- Over 80% energy saving against halogen
- Cool and warm white options available
- 350° rotation and 90° tilt

✓ JC14159WH



5 year
ext. warranty*

Classification

⊕ Class 1
IP20 | 240V

LED

3000K | CRI: Ra (85)
4000K | CRI: Ra (85)


Finishes

White (WH)

Construction

Body: Aluminium
Lens: Polycarbonate

JC14158 / JC14159

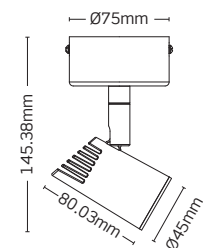

Code	Description	Col temp.	Dim.	Watt	Lumens	LPCW
JC14159WH	Starspot Surface 500	3000K	No	7W	450	64
JC14158WH	Starspot Surface 500	4000K	No	7W	480	69

*Requires online registration.

All data sheets and installation sheets
available at jcc.co.uk