



JC14162SCH

Classification

Class 1
IP20 | 240V

LED

3000K | CRI: Ra (85)
4000K | CRI: Ra (85)


Finishes

Satin Chrome (SCH), White (WH)

Construction

Body: Aluminium
Lens: Polycarbonate

JC14162 / JC14163

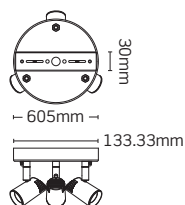

All data sheets and installation sheets
available at jcc.co.uk

Starspot™ 500 Surface Triple

High performance LED surface mounted spotlights

- Exceeds 50W halogen light output
- Over 80% energy saving against halogen
- Zero maintenance, no need to relamp
- 350° rotation and 90° tilt

JC14162WH



Code	Description	Col temp.	Dim.	Watt	Lumens	LPCW
JC14163	Starspot Surface 500 Triple Plate	3000K	No	3 x 7W	1350	64
JC14162	Starspot Surface 500 Triple Plate	4000K	No	3 x 7W	1440	69

For Satin Chrome add **SCH** suffix, for White add **WH** suffix.

*Requires online registration.