

LED Undercabinet

Direct replacement for T5 fluorescent

- End-to-end connection
- Three link leads available in 250mm, 500mm and 1000mm lengths
- Slim line profile
- On/off switch on each luminaire
- Supplied as standard with 1000mm mains cable



NEW New product for 2018

3 year ext. warranty*

120° beam angle

Classification

Class 2
IP20 | 240V

LED

3000K | CRI: Ra (80)
4000K | CRI: Ra (80)

Finishes

White


Construction

Body: Polycarbonate
Diffuser: Polycarbonate
Clips: Polycarbonate

Accessories

Link leads- 250mm (JC83309),
500mm (JC83310),
1000mm (JC83311)

1. JC83302 / JC83301
2. JC83304 / JC83303
3. JC83306 / JC83305
4. JC83308 / JC83307

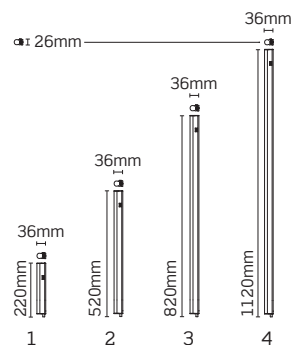

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC83302	220mm Undercabinet LED T5 Batten	3000K	No	3W	300	100
JC83301	220mm Undercabinet LED T5 Batten	4000K	No	3W	320	107
JC83304	520mm Undercabinet LED T5 Batten	3000K	No	8W	820	103
JC83303	520mm Undercabinet LED T5 Batten	4000K	No	8W	920	115
JC83306	820mm Undercabinet LED T5 Batten	3000K	No	12W	1370	114
JC83305	820mm Undercabinet LED T5 Batten	4000K	No	12W	1480	123
JC83308	1120mm Undercabinet LED T5 Batten	3000K	No	15W	1650	110
JC83307	1120mm Undercabinet LED T5 Batten	4000K	No	15W	1750	117
JC83309	LED Undercabinet Link Lead: 250mm	-	-	-	-	-
JC83310	LED Undercabinet Link Lead: 500mm	-	-	-	-	-
JC83311	LED Undercabinet Link Lead: 1000mm	-	-	-	-	-

*Requires online registration.

All data sheets and installation sheets available at jcc.co.uk