



2 year
product guarantee

Low Voltage Undershef

Low profile downlight

- Can be recessed into shelves or surface mounted
- Sold individually
- Chrome and white finishes available
- Lamp included



Classification

Class 3
IP20 | 12V

Finishes

Chrome (**CH**), White (**WH**)

Lamp

20W G4 (included)


Construction

Body: Steel
Lens: Heat resistant glass

Installation

Method of fix: surface
mounted/recessed
Cut out Ø: 64mm

JC3014

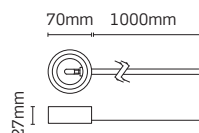

All data sheets and installation sheets
available at jcc.co.uk

Code	Description	Lamp
JC3014	Low Voltage Undershef Downlight	G4 20W
JC4030	10-60VA transformer for JC3014	-

For Chrome add **CH** suffix, for white add **WH** suffix