



5 year
ext. warranty*



Sensing
options available



Emergency
options available

RadiaLED® Style 14W

High performance LED wall & ceiling light

- 28W CFL replacement
- IP44 protection against dust and moisture
- Ideal for corridor and stairwell applications
- Smooth and even light distribution



Classification

⚡ Class 1
IP44 | 240V
IK09 impact rating

LED

4000K | CRI: Ra (80)

Finishes


White Opal

Construction

Body: Steel
Diffuser: Polycarbonate

JC234202

122.5mm

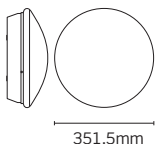

All data sheets and installation sheets
available at jcc.co.uk

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC234202	RadiaLED Style	4000K	No	14W	1250	89
JC234202MW	RadiaLED Style Micro. on/off sensor	4000K	No	14W	1250	89
JC234202EM	RadiaLED Style emergency	4000K	No	14W	1250	89
JC234202EM/MW	RadiaLED Style Micro. on/off sensor emerg.	4000K	No	14W	1250	89

*Requires online registration.