


RadiaLED® Style 32W

High performance LED wall & ceiling light

- Outperforms traditional 38W CFL
- Up to 90 lumens per circuit Watt
- IP44 protection against dust and moisture
- Ideal for corridor and stairwell applications
- Smooth and even light distribution



 5 year ext. warranty*

 Sensing options available

 Emergency options available

Classification

⊕ Class 1
IP44 | 240V
IK09 impact rating

LED

4000K | CRI: Ra (80)

Finishes


White Opal

Construction

Body: Steel
Diffuser: Polycarbonate

JC234203

147mm

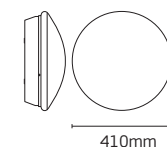

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC234203	RadiaLED Style	4000K	No	30W	2900	97
JC234203MW	RadiaLED Style Micro. on/off sensor	4000K	No	30W	2900	97
JC234203EM	RadiaLED Style emergency	4000K	No	30W	2900	97
JC234203EM/MW	RadiaLED Style Micro. on/off sensor em.	4000K	No	30W	2900	97

*Requires online registration.

All data sheets and installation sheets available at jcc.co.uk