

RadiaLED® Optimum 8W


50% energy saving against 16W 2D fluorescent

- Twin conduit side entry points
- Dusk to dawn on/off photocell options available
- IP65 weather resistant
- Rim accessories available, see p.219
- 83 lumens per circuit Watt



^ With optional rim (sold separately)
JC23330SCH

 5 year ext. warranty*


 Sensing options available

 Emergency options available



^ For alternative rim options, see p.219

Classification

 Class 1
IP65 | 240V

LED

4000K | CRI: Ra (80)

Finishes

White Opal (**WOP**)

Construction

Body: Polycarbonate
Diffuser: Polycarbonate


Accessories

For rim options, see page 219.

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC23331WOP	RadiaLED Opt.	4000K	No	8W	660	83
JC23331WOPPC	RadiaLED Opt. on/off photocell	4000K	No	8W	660	83
JC23333WOP	RadiaLED Opt. micro. on/off	4000K	No	8W	660	83
JC23332WOP	RadiaLED Opt. emergency	4000K	No	8W	660	83
JC23332WOPPC	RadiaLED Opt. on/off photocell emerg.	4000K	No	8W	660	83
JC23334WOP	RadiaLED Opt. micro. on/off emerg.	4000K	No	8W	660	83

*Requires online registration.

JC23331WOP

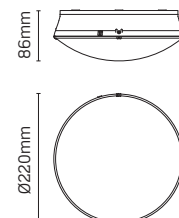

All data sheets and installation sheets available at jcc.co.uk