



RadiaLED® Optimum 14W

50% energy saving against 28W 2D fluorescent


-  5 year ext. warranty*
-  Sensing options available
-  Emergency options available

- Twin conduit side entry points
- Dusk to dawn on/off photocell options available
- IP65 weather resistant
- Anti-vandal construction
- Rim accessories available, see p.219
- 79 lumens per circuit Watt



^ For alternative rim options, see p.219

Classification

 Class 1
IP65 | 240V

LED

4000K | CRI: Ra (80)

Finishes

White Opal (**WOP**)


 
Construction

Body: Polycarbonate
Diffuser: Polycarbonate

Accessories

For rim options, see page 219.

JC23341WOP

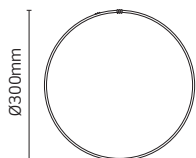

All data sheets and installation sheets available at jcc.co.uk



^ With optional rim (sold separately)
JC23340SCH

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC23341WOP	RadiaLED Opt.	4000K	No	14W	1100	79
JC23341WOPPC	RadiaLED Opt. on/off photocell	4000K	No	14W	1100	79
JC23343WOP	RadiaLED Opt. micro. dimming	4000K	-	14W	1100	79
JC23342WOP	RadiaLED Opt. emergency	4000K	No	14W	1100	79
JC23342WOPPC	RadiaLED Opt. on/off photocell emerg.	4000K	No	14W	1100	79
JC23344WOP	RadiaLED Opt. micro. on/off emerg.	4000K	No	14W	1100	79

*Requires online registration.