


RadiaLED® Optimum 19W


50% energy saving against 38W 2D fluorescent

- Twin conduit side entry points
- Dusk to dawn on/off photocell options available
- IP65 weather resistant
- Anti-vandal construction
- Rim accessories available, see p.219
- 84 lumens per circuit Watt



^ With optional rim -
JC23340SCH

 5 year
ext. warranty*


 Sensing
options available

 Emergency
options available



^ For alternative rim options,
see p.219

Classification

 Class 1
IP65 | 240V

LED

4000K | CRI: Ra (80)

Finishes

White Opal (WOP)

Construction

Body: Polycarbonate
Diffuser: Polycarbonate


 
Accessories

For rim options, see page 219.

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC23351WOP	RadiaLED Opt.	4000K	No	19W	1600	84
JC23351WOPPC	RadiaLED Opt. on/off photocell	4000K	No	19W	1600	84
JC23353WOP	RadiaLED Opt. micro. on/off	4000K	No	19W	1600	84
JC23352WOP	RadiaLED Opt. emergency	4000K	No	19W	1600	84
JC23352WOPPC	RadiaLED Opt. on/off photocell emerg.	4000K	No	19W	1600	84
JC23354WOP	RadiaLED Opt. micro. on/off emerg.	4000K	No	19W	1600	84

*Requires online registration.

JC23351WOP

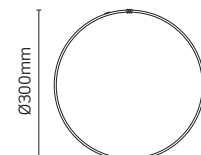

All data sheets and installation sheets
available at jcc.co.uk