



5 year
ext. warranty*



Sensing
options available



Emergency
options available

RadiaLED® Utility 21W

Direct 38W 2D replacements

- IP65 weather resistant
- Anti-vandal construction
- Corrosion resistant, suitable for coastal locations
- Opal or prismatic polycarbonate diffuser options
- Dusk to dawn on/off photocell options available
- Up to 95 lumens per circuit Watt

✓ JC23402WOP



Classification

⊕ Class 1
IP65 | 240V

LED

4000K | CRI: Ra (80)


Finishes

White Opal (**WOP**),
White Prismatic (**WPR**)

Construction

Body: Polycarbonate
Diffuser: Polycarbonate

JC23402

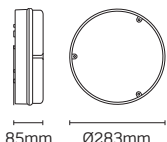

All data sheets and installation sheets
available at jcc.co.uk

Code	Description	Col temp.	Dim.	Watt	Lumens (WOP)	Lumens (WPR)
JC23402	RadiaLED Utility	4000K	No	21W	1350	2000
JC23432	RadiaLED Utility on/off photocell	4000K	No	21W	1350	2000
JC23412	RadiaLED Utility microwave on/off	4000K	No	21W	1350	2000
JC23422	RadiaLED Utility microwave dimming	4000K	-	21W	1350	2000
JC23402EM	RadiaLED Utility emergency	4000K	No	21W	1350	2000
JC23432EM	RadiaLED Utility on/off photocell em.	4000K	No	21W	1350	2000
JC23412EM	RadiaLED Utility microwave emergency	4000K	No	21W	1350	2000
JC23422EM	RadiaLED Utility microwave dimming em.	4000K	-	21W	1350	2000

For White Opal add **WOP** suffix, for White Prismatic add **WPR** suffix.

*Requires online registration.