


Cylindrical Up/Down Wall Light


Architectural exterior LED lighting

- Durable die-cast aluminium construction
- Surface mountable up/down wall light
- IP54 protection against dust and moisture
- Stylish, contemporary design
- Matching colour temperature and finish to the Architectural Exterior range

NEW New product for 2018

 3 year ext. warranty*

 44° beam angle

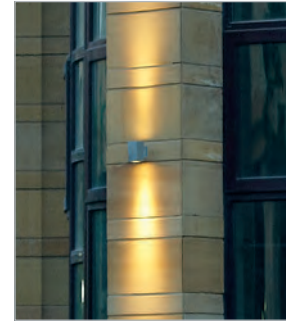

 Two directional light


✓ JC17016



✓ JC17015



Classification

 Class 1
IP54 | 240V

LED

3000K | CRI: Ra (80)


Finishes

Anthracite


Construction

Body: Aluminium
Lens: Glass

JC17015

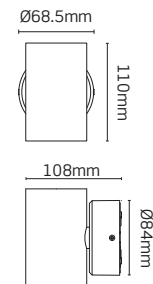

JC17016

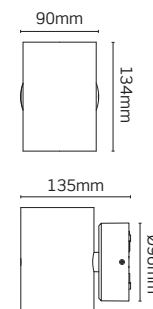

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC17015	Cylindrical Up/down	3000K	No	8W	400	50
JC17016	Cylindrical Up/down	3000K	No	14W	800	57

*Requires online registration.

All data sheets and installation sheets available at jcc.co.uk