

# Rectangular Wall Light

## Architectural exterior LED lighting

- Two directional light output
- Durable die-cast aluminium construction
- IP54 protection against dust and moisture
- Stylish, contemporary design
- LED wall light with matching colour temperature and finish to the Architectural Exterior range

✓ JC17011



NEW

New product  
for 2018



3 year  
ext. warranty\*



73°  
beam angle



^ Two directional light

### Classification

⚡ Class 1  
IP54 | 240V

### LED

3000K | CRI: Ra (80)


### Finishes

Anthracite

### Construction

Body: Aluminium  
Lens: Glass

### JC17011

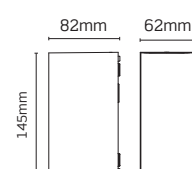

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC17011	Rectangular Up/Down	3000K	No	14W	1000	71

\*Requires online registration.

All data sheets and installation sheets  
available at [jcc.co.uk](http://jcc.co.uk)