

NEWNew product
for 20183 year
ext. warranty*73°
beam angle

Rectangular Wall Light

Architectural exterior LED lighting

- Single direction light
- Durable die-cast aluminium construction
- IP54 protection against dust and moisture
- Stylish, contemporary design
- LED wall light with matching colour temperature and finish to the Architectural Exterior range

✓ JC17012



Classification

⊕ Class 1
IP54 | 240V

LED

3000K | CRI: Ra (80)


Finishes

Anthracite

Construction

Body: Aluminium
Lens: Glass

JC17012

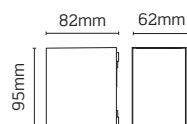

All data sheets and installation sheets
available at jcc.co.uk

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC17012	Rectangular Single Direction Wall Light	3000K	No	7W	550	78

*Requires online registration.