

Up/Down Light Box


Architectural exterior LED lighting


- Durable die-cast aluminium construction
- Surface mountable up/down wall light
- IP54 protection against dust and moisture
- LED wall light with matching colour temperature and finish to the Architectural Exterior range


✓ JC17010BLK



NEW New product for 2018


 3 year ext. warranty*

 96° beam angle

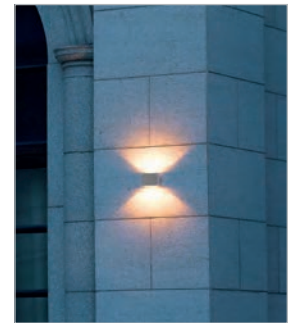

✓ Two directional light

Classification

 Class 1
IP54 | 240V

LED

3000K | CRI: Ra (80)



Finishes

Anthracite (**BLK**), White (**WH**)

Construction

Body: Aluminium
Lens: Polycarbonate

  JC17010



Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC17010	Up/Down Box	3000K	No	5W	160	32

For Anthracite add **BLK** suffix, for White add **WH** suffix.

*Requires online registration.

All data sheets and installation sheets available at jcc.co.uk