

NEW

New product  
for 20183 year  
ext. warranty\*40°  
beam angle

# Wall Spot

## Architectural exterior LED lighting

- Durable die-cast aluminium construction
- IP65 protection weather resistant
- Stylish, contemporary design
- LED wall light with matching colour temperature and finish to the Architectural Exterior range



### Classification

⊕ Class 1  
IP65 | 240V

### LED

3000K | CRI: Ra (80)


### Finishes

Anthracite

### Construction

Body: Aluminium  
Lens: Polycarbonate

### JC17042

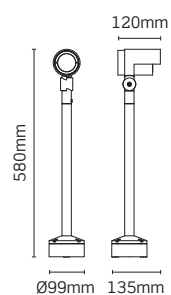

All data sheets and installation sheets  
available at [jcc.co.uk](http://jcc.co.uk)

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC17042	Wall Spot Long	3000K	No	10W	750	75

\*Requires online registration.