

NiteLED™ Dome Wall Lights

Low wattage LED exterior lighting

- Direct 42W halogen GLS replacement
- 8.5W mains driven LED, no driver required
- Zero maintenance, no need to relamp
- Plain and louvred variants available
- Black and stainless steel versions available

✓ JC39429SS



2 year
product guarantee



See p.298-301
for matching bollards



✓ JC39429BLK



✓ Matching bollards available,
see p.298-301

Classification

⊕ Class 1
IP44 | 240V

LED

4000K | CRI: Ra (80)

Finishes

Black (**BLK**), Stainless Steel (**SS**)


Construction

Body: Aluminium
Lens: Polycarbonate

Accessories

Matching bollards available,
see p.298-301

JC39429

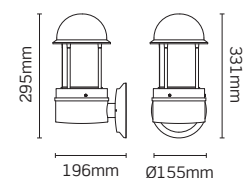

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC39429	NiteLED Dome Wall Light - plain	4000K	No	8.5W	200	24

For Black add **BLK** suffix, for Stainless Steel add **SS** suffix.