

NiteLED™ Dome Wall Lights

Low wattage LED exterior lighting



2 year product guarantee



See p.298-301 for matching bollards



JC39428BLK



Matching bollards available, see p.298-301

Classification

Class 1
IP44 | 240V

LED

4000K | CRI: Ra (80)

Finishes

Black (BLK), Stainless Steel (SS)


Construction

Body: Aluminium
Lens: Polycarbonate

Accessories

Matching bollards available, see p.298-301

JC39428

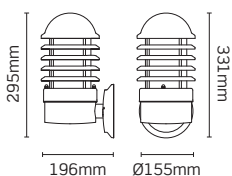

All data sheets and installation sheets available at jcc.co.uk

- Direct 42W halogen GLS replacement
- Plain diffuser for a wider spread of light
- 8.5W mains driven LED, no driver required
- Zero maintenance, no need to relamp
- Plain and louvred variants available
- Black and stainless steel versions available

JC39428SS



Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC39428	NiteLED Dome Wall Light - louvred	4000K	No	8.5W	200	24

For Black add **BLK** suffix, for Stainless Steel add **SS** suffix.