



New product
for 2018



3 year
ext. warranty*



110°
beam angle



JC45205WH

Classification

Class 1
IP44 | 240V

LED

4000K | CRI: Ra (70)

PIR Detection range

Detection distance: 5 - 8m
Max height: 3m
Detection range: 120°

PIR Hold time

Adjustable: 10 seconds -
10 minutes

Ambient light sensitivity

Adjustable: 10 lux - 2000 lux


Finishes

Black (**BLK**), White (**WH**)

Construction

Body: Aluminium
Lens: Toughened glass
Bracket: Galvanised steel

JC45205

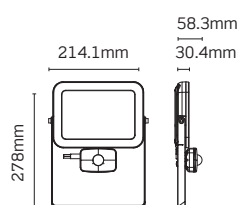

All data sheets and installation sheets
available at jcc.co.uk

LED Floodlight 30W PIR

High performance domestic floodlight

- Highly efficient at 93 Lumens per circuit Watt
- Angled bracket for easy installation
- Driverless technology
- Supplied pre-wired with 800mm flex
- Available in black and white colour variants
- Adjustable PIR detection

JC45205BLK



Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC45205	LED Floodlight with PIR	4000K	No	30W	2800	93

For Black add **BLK** suffix, for White add **WH** suffix.

*Requires online registration.