

NEWNew product
for 20183 year
ext. warranty*110°
beam angle

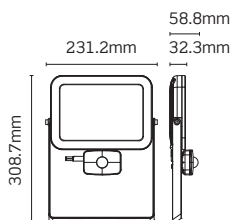
✓ JC45207BLK

ClassificationClass 1
IP44 | 240V**LED**

4000K | CRI: Ra (70)

PIR Detection rangeDetection distance: 5 - 8m
Max height: 3m
Detection range: 120°**PIR Hold time**Adjustable: 10 seconds -
10 minutes**Ambient light sensitivity**

Adjustable: 10 lux - 2000 lux

FinishesBlack (**BLK**), White (**WH**)**Construction**Body: Aluminium
Lens: Toughened glass
Bracket: Galvanised steel**JC45207**All data sheets and installation sheets
available at jcc.co.uk

LED Floodlight 50W PIR

High performance domestic floodlight

- Highly efficient at 90 Lumens per circuit Watt
- Angled bracket for easy installation
- Driverless technology
- Supplied pre-wired with 800mm flex
- Available in black and white colour variants
- Adjustable PIR detection

✓ JC45207WH



Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC45207	LED Floodlight with PIR	4000K	No	50W	4500	90

For Black add **BLK** suffix, for White add **WH** suffix.

*Requires online registration.