


Toughflood™ 80W

High output commercial LED floodlight


- Ultra efficient, 120 Lumens per circuit Watt
- Instant start-up for use with occupancy sensors
- Supplied pre-wired with 1.2m flex
- IP65 protection against dust and moisture
- Ideal for mounting heights of up to 6m



 5 year
ext. warranty*

 60°
beam angle

Classification

 Class 1
IP65 | 240V

LED

4000K | CRI: Ra (80)


Finishes

Grey

Construction

Body: Aluminium
Lens: Polycarbonate
Bracket: Galvanised steel

JC45130

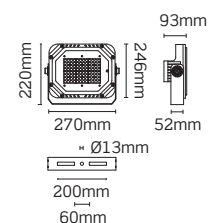

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC45130	Toughflood	4000K	No	80W	9600	120

*Requires online registration.

All data sheets and installation sheets
available at jcc.co.uk