



5 year  
ext. warranty\*



60°  
beam angle

# Toughflood™ 100W

## High output commercial LED floodlight

- Ultra efficient, 120 Lumens per circuit Watt
- Instant start-up for use with occupancy sensors
- Supplied pre-wired with 1.2m flex
- IP65 protection against dust and moisture
- Ideal for mounting heights of up to 6m



### Classification

⚡ Class 1  
IP65 | 240V

### LED

4000K | CRI: Ra (80)


### Finishes

Grey

### Construction

Body: Aluminium  
Lens: Polycarbonate  
Bracket: Galvanised steel

JC45131

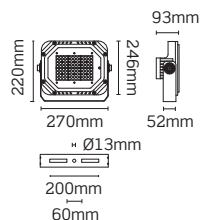

All data sheets and installation sheets  
available at [jcc.co.uk](http://jcc.co.uk)

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC45131	Toughflood	4000K	No	100W	12,000	120

\*Requires online registration.