



5 year
ext. warranty*



60°
beam angle

Toughflood™ 200W

High output commercial LED floodlight

- Ultra efficient, 120 Lumens per circuit Watt
- IP65 as standard
- Supplied pre-wired with 1.2m flex
- Instant start-up for use with occupancy sensors
- Ideal for mounting heights of up to 10m



Classification

⊕ Class 1
IP65 | 240V

LED

4000K | CRI: Ra (80)


Finishes

Grey

Construction

Body: Aluminium
Lens: Polycarbonate
Bracket: Galvanised steel

JC45133

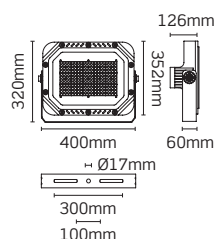

All data sheets and installation sheets
available at jcc.co.uk

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC45133	Toughflood	4000K	No	200W	24,000	120

*Requires online registration.