

Toughflood™ High Output

Ultra efficient 100W & 150W directional floodlight

- Up to 142 Lumens per circuit Watt
- 5 different beam angle options available
- LED modules can be adjusted individually
- IP66 weather resistance
- Features 10KV Surge protector as standard
- Produced to order, contact JCC customer services on **01243 838999**



NEW

New product for 2018



5 year ext. warranty*



Multiple lens options available



Produced to order call 01243 838999

Classification

⊕ Class 1
IP66 | 240V
IK10

LED

4000K | CRI: Ra (70)


Finishes

Black


Construction

Body: Aluminium
Lens: Polycarbonate
Bracket: Galvanised steel

 JC45220



JC45221

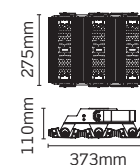

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC45220/30	Toughflood 30° Symmetric	4000K	No	100W	14,200	142
JC45220/45	Toughflood 45° Symmetric	4000K	No	100W	14,100	141
JC45220/70	Toughflood 70° Symmetric	4000K	No	100W	14,100	141
JC45220/711	Toughflood 70x110° Symmetric	4000K	No	100W	14,200	142
JC45220/613	Toughflood 60x130° Asymmetric	4000K	No	100W	14,200	142
JC45221/30	Toughflood 30° Symmetric	4000K	No	150W	21,000	140
JC45221/45	Toughflood 45° Symmetric	4000K	No	150W	21,100	141
JC45221/70	Toughflood 70° Symmetric	4000K	No	150W	21,100	141
JC45221/711	Toughflood 70x110° Symmetric	4000K	No	150W	21,000	140
JC45221/613	Toughflood 60x130° Asymmetric	4000K	No	150W	21,300	142

Produced to order, contact JCC customer services on **01243 838999**.

*Requires online registration.

All data sheets and installation sheets available at jcc.co.uk