



New product  
for 2018



5 year  
ext. warranty\*



Multiple lens  
options available



Produced to order  
call 01243 838999

# Toughflood™ High Output

## Ultra efficient 300W directional floodlight

- Ultra efficient at 141 Lumens per circuit Watt
- 5 different beam angle options available
- LED modules can be adjusted individually
- IP66 weather resistance
- Features 10KV Surge protector as standard
- Produced to order, contact JCC customer services on **01243 838999**



### Classification

⊕ Class 1  
IP66 | 240V  
IK10

### LED

4000K | CRI: Ra (70)


### Finishes

Black

### Construction

Body: Aluminium  
Lens: Polycarbonate  
Bracket: Galvanised steel

### JC45223

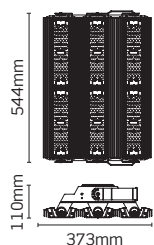

All data sheets and installation sheets  
available at [jcc.co.uk](http://jcc.co.uk)

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC45223/30	Toughflood 30° Symmetric	4000K	No	300W	42,000	140
JC45223/45	Toughflood 45° Symmetric	4000K	No	300W	42,100	140
JC45223/70	Toughflood 70° Symmetric	4000K	No	300W	42,100	140
JC45223/711	Toughflood 70x110° Symmetric	4000K	No	300W	42,200	141
JC45223/613	Toughflood 60x130° Asymmetric	4000K	No	300W	42,300	141

Produced to order, contact JCC customer services on **01243 838999**.

\*Requires online registration.