


# Toughflood™ High Output

## Ultra efficient 450W directional floodlight

- Up to 142 Lumens per circuit Watt
- 5 different beam angle options available
- LED modules can be adjusted individually
- IP66 weather resistance
- Features 10KV Surge protector as standard
- Produced to order, contact JCC customer services on **01243 838999**

**NEW** New product for 2018


 5 year ext. warranty\*

 Multiple lens options available

 Produced to order call 01243 838999



### Classification

 Class 1  
IP66 | 240V  
IK10

### LED

4000K | CRI: Ra (70)


### Finishes

Black

### Construction

Body: Aluminium  
Lens: Polycarbonate  
Bracket: Galvanised steel

### JC45224

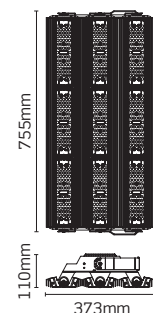

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC45224/30	Toughflood 30° Symmetric	4000K	No	450W	63,100	140
JC45224/45	Toughflood 45° Symmetric	4000K	No	450W	63,000	140
JC45224/70	Toughflood 70° Symmetric	4000K	No	450W	63,100	140
JC45224/711	Toughflood 70x110° Symmetric	4000K	No	450W	63,300	141
JC45224/613	Toughflood 60x130° Asymmetric	4000K	No	450W	63,700	142

Produced to order, contact JCC customer services on **01243 838999**.

\*Requires online registration.

All data sheets and installation sheets available at [jcc.co.uk](http://jcc.co.uk)