



New product
for 2018



5 year
ext. warranty*



Multiple lens
options available



Produced to order
call 01243 838999

Toughflood™ High Output

Ultra efficient 600W directional floodlight

- Up to 141 Lumens per circuit Watt
- 5 different beam angle options available
- LED modules can be adjusted individually
- IP66 weather resistance
- Features 10KV Surge protector as standard
- Produced to order, contact JCC customer services on **01243 838999**



Classification

⊕ Class 1
IP66 | 240V
IK10

LED

4000K | CRI: Ra (70)


Finish

Black

Construction

Body: Aluminium
Lens: Polycarbonate
Bracket: Galvanised steel

JC45225

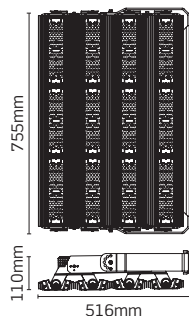

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC45225/30	Toughflood 30° Symmetric	4000K	No	600W	84,100	140
JC45225/45	Toughflood 45° Symmetric	4000K	No	600W	84,100	140
JC45225/70	Toughflood 70° Symmetric	4000K	No	600W	84,200	140
JC45225/711	Toughflood 70x110° Symmetric	4000K	No	600W	84,700	141
JC45225/613	Toughflood 60x130° Asymmetric	4000K	No	600W	84,700	140

Produced to order, contact JCC customer services on **01243 838999**.