

Tapered Bollard

Architectural exterior LED lighting

- Durable die-cast aluminium construction
- IP65 protection against dust and moisture
- Matching colour temperature and finish to the Architectural Exterior range
- Stylish, contemporary design



NEW

New product
for 20183 year
ext. warranty*50°
beam angle

Classification

⊕ Class 1
IP65 | 240V

LED

3000K | CRI: Ra (80)


Finishes

Anthracite

Construction

Body: Aluminium
Diffuser: Polycarbonate

JC17018

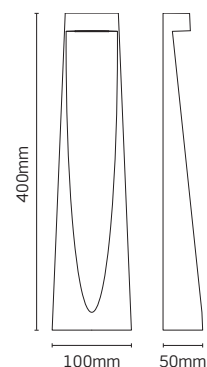

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC17018	Tapered Bollard	3000K	No	7W	303	43

*Requires online registration.

All data sheets and installation sheets
available at jcc.co.uk