

NiteLED™ Round Bollard

Low wattage LED exterior lighting

- External base fixing for faster installation
- Durable aluminium construction
- Integral LED driver
- Instant start up, no warm up time
- Zero maintenance, no need to relamp



2 year
product guarantee

Classification

⊕ Class 1
IP54 | 240V

LED

4000K | CRI: Ra (80)

Finishes

Anthracite


Construction

Body: Aluminium
Diffuser: Polycarbonate

Accessories

Root mounting kit (JC39412)

JC39404

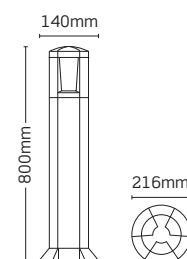

All data sheets and installation sheets
available at jcc.co.uk

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC39404	NiteLED Round Bollard	4000K	No	6W	300	50
JC39412	Root mounting kit (Round Bollard)	-	-	-	-	-