

NiteLED™ Dome Bollard

Low wattage LED exterior lighting

- Direct 42W halogen GLS replacement
- Zero maintenance, no need to relamp
- Instant start up, no warm up time



2 year
product guarantee




Matching wall light available,
see p.252

✓ JC39427BLK



✓ JC39426BLK

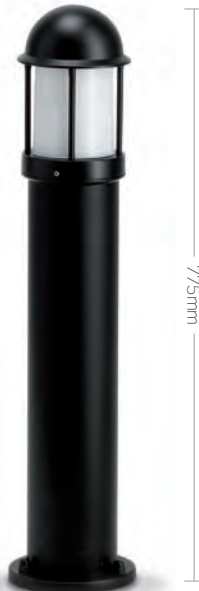

✓ JC39425BLK



Classification

⊕ Class 1
IP44 | 240V

LED

4000K | CRI: Ra (80)

Finishes

Black (**BLK**), for Stainless Steel (**SS**) see p.300

Construction

Body: Aluminium
Diffuser: Polycarbonate

Accessories

Root mounting kit (JC39224)

JC39224

Ø170mm



JC39427BLK

Ø155mm



Ø166mm

JC39426BLK

Ø155mm



Ø166mm

JC39425BLK

Ø155mm



Ø166mm

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC39425BLK	Short (475mm)	4000K	No	8.5W	200	24
JC39426BLK	Medium (775mm)	4000K	No	8.5W	200	24
JC39427BLK	Tall (1275mm)	4000K	No	8.5W	200	24
JC39224	Root mounting kit	-	-	-	-	-