



2 year product guarantee

# NiteLED™ Dome Bollard

## Low wattage LED exterior lighting

- Direct 42W halogen GLS replacement
- Zero maintenance, no need to relamp
- Instant start up, no warm up time



Matching wall light available, see p.253

### Classification

Class 1  
IP44 | 240V

### LED

4000K | CRI: Ra (80)

### Finishes



Black (BLK), for Stainless Steel (SS) see p.301

### Construction

Body: Aluminium  
Diffuser: Polycarbonate

### Accessories

Root mounting kit (JC39224)

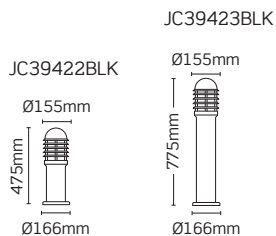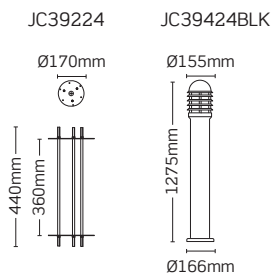

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC39422BLK	Short (475mm)	4000K	No	8.5W	200	24
JC39423BLK	Medium (775mm)	4000K	No	8.5W	200	24
JC39424BLK	Tall (1275mm)	4000K	No	8.5W	200	24
JC39224	Root mounting kit	-	-	-	-	-

All data sheets and installation sheets available at [jcc.co.uk](http://jcc.co.uk)