

# NiteLED™ Dome Bollard

## Low wattage LED exterior lighting

- Direct 42W halogen GLS replacement
- Zero maintenance, no need to relamp
- Instant start up, no warm up time



2 year  
product guarantee



Matching wall light available,  
see p.252

### Classification

Class 1  
IP44 | 240V

### LED

4000K | CRI: Ra (80)

### Finishes


Stainless steel (**SS**), for Black (**BLK**) see p.298

### Construction

Body: Steel  
Diffuser: Polycarbonate

### Accessories

Root mounting kit (JC39224)

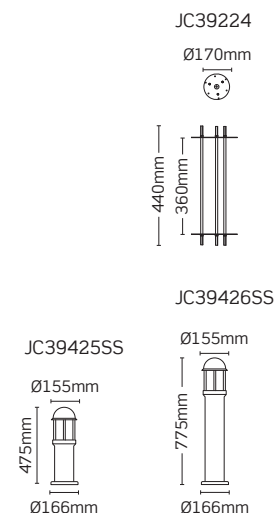

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC39425SS	Short (475mm)	4000K	No	8.5W	200	24
JC39426SS	Medium (775mm)	4000K	No	8.5W	200	24
JC39224	Root mounting kit	-	-	-	-	-