

# Inground LED

## Architectural exterior LED lighting

- Durable exterior in ground fitting
- Matching colour temperature to the Architectural Exterior range
- IP67 protection against dust and the effects of immersion
- High quality stainless steel construction
- 500kg static weight limit



125mm

NEW

New product  
for 2018



3 year  
ext. warranty\*



24°  
beam angle

### Classification

⊕ Class 1  
IP67 | 240V

### LED

3000K | CRI: Ra (80)


### Finishes

Stainless steel

### Construction

Body: Aluminium  
Diffuser: Glass  
Bezel: Stainless steel

### JC17029

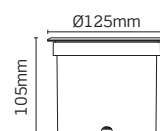

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC17029	IP67 Inground walkover	3000K	No	7W	600	86

\*Requires online registration.

All data sheets and installation sheets  
available at [jcc.co.uk](http://jcc.co.uk)