



New product
for 2018



3 year
ext. warranty*



30°
beam angle

Inground LED

Architectural exterior LED lighting

- High output exterior in ground fitting
- Matching colour temperature to the Architectural Exterior range
- IP67 protection against dust and the effects of immersion
- High quality stainless steel construction
- 500kg static weight limit



240mm

Classification

⊕ Class 1
IP67 | 240V

LED

3000K | CRI: Ra (80)


Finishes

Stainless steel

Construction

Body: Aluminium
Diffuser: Glass
Bezel: Stainless steel

JC17034

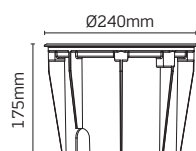

All data sheets and installation sheets
available at jcc.co.uk

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC17034	IP67 Inground walkover	3000K	No	24W	1800	75

*Requires online registration.