



2 year
product guarantee

NiteLED™ Walkover

6W stainless steel LED in-ground light

- External base fixing for faster installation
- High quality stainless steel construction
- Zero maintenance, no need to relamp
- Supplied pre-wired



149mm

Classification

⚡ Class 1
IP67 | 240V

LED

4000K | CRI: Ra (70)

Finishes

Stainless steel


Construction

Body: Aluminium
Diffuser: Clear glass
Bezel: Stainless steel

Installation

Cut out Ø:
Width - 136mm
Depth - 125mm

JC39414

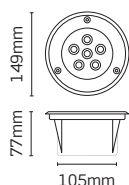

All data sheets and installation sheets
available at jcc.co.uk

Code	Description	Col temp.	Watt	Lumens	LpcW
JC39414	NiteLED Walkover	4000K	6W	360	60